


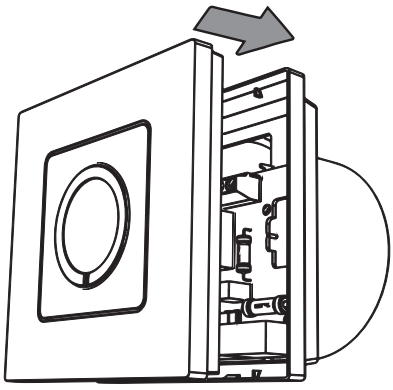


Danfoss A/S 6430 Nordborg Denmark						<i>Icon™</i> Dial 230W OW Max. load: 10W/50mA					
L		N		N		Load NC		Load NO			
50-60 Hz		220-240V		M							

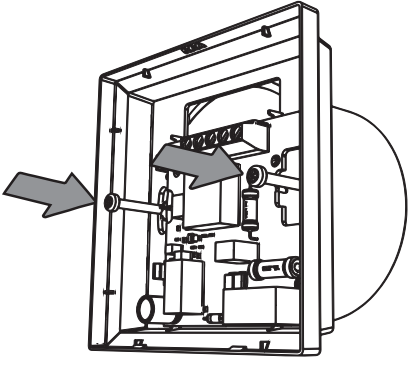


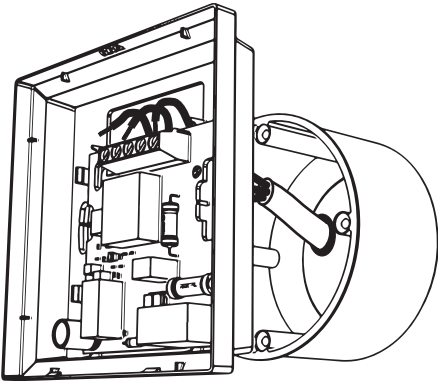


7.

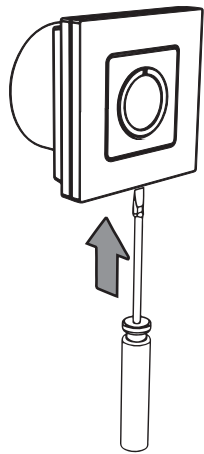



8.

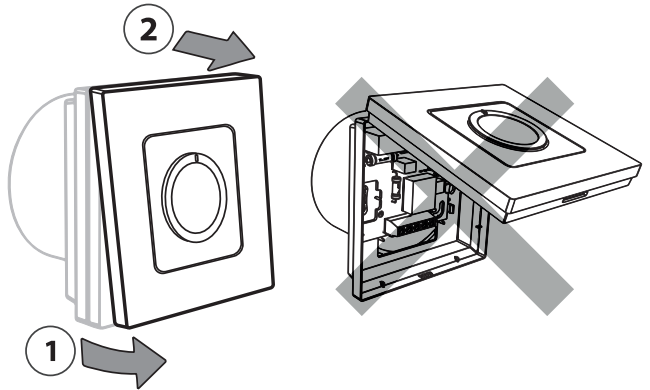

9.

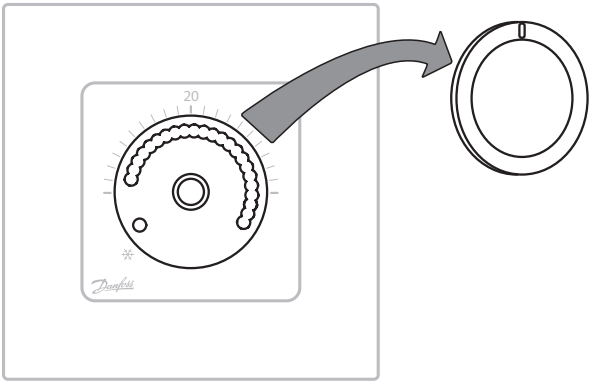

10.

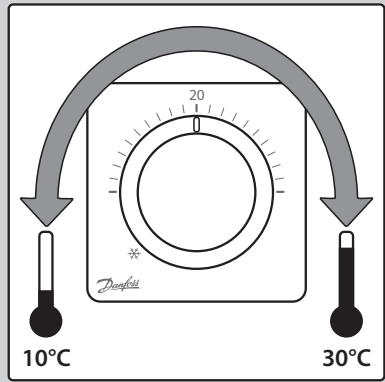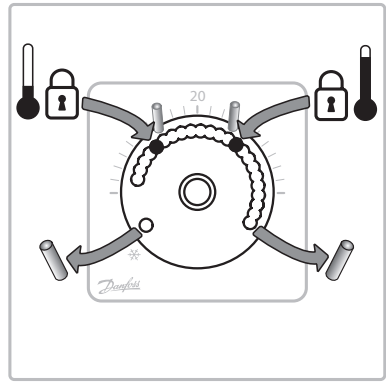

❄ = 5°C

13658 000 00 Manual Installation WRT Dial 230 F86 OW

ENGINEERING
TOMORROW



Installation & User Guide

Danfoss *Icon*™ Dial Room Thermostat

VICUY10F/088N3653

www.icon.danfoss.com